

# rehlko



Kohler Engines  
is now Rehlko

## Command PRO® ECH440

Gasoline Engines

10.5 kW | 14 hp

Discover the configurable solution  
for all the equipment in your fleet.  
Command PRO engines: the most factory options.



# Always *running*. Always *earning*.

Starting the engine is the last thing you or your customer should worry about. That’s why you want the REHLKO Command PRO® EFI ECH440 engine powering every piece of equipment. The ECH440 starts like your car, with no choking. There’s no carb, so there’s no carb downtime. Your equipment is always running—and earning—and your customers are more productive. Plus, REHLKO EFI engines save cash at the pump and save time on refueling.

## Standard features

- No choke—starts just like your car

No carburetor —no carburetor problems

Efi diagnostic software provides quick and easy troubleshooting to minimize downtime\*

Easy access to all routine maintenance points

3-Year unlimited-hour limited warranty
- Less time refueling and better fuel economy than similarly sized carbureted engines

Automatically optimizes for fuel grade, fuel quality and altitude

Reduced carbon footprint—less fuel means less carbon produced

MODEL		ECH440
POWER @ 3600 rpm	max. hp (kW)	14 (10.5)
DISPLACEMENT	cu in (cc)	26.2 (429)
BORE	in (mm)	3.5 (89)
STROKE	in (mm)	2.7 (69)
PEAK TORQUE @ rpm	ft-lb (Nm)	22.7 (30.8) @ 2800
COMPRESSION RATIO		8.3:1
DRY WEIGHT	lb (kg)	72.8 (33)
OIL CAPACITY	U.S. qt (L)	1.16 (1.1)
FUEL CAPACITY	U.S. qt (L)	7.4 (7)
LUBRICATION		SPLASH
DIMENSIONS* L x W x H	in (mm)	12.7 x 17.8 x 18.4 (324 x 452 x 467)
EMISSION COMPLIANCE		EU STAGE V, EPA PHASE III, CARB PHASE III, CHINA PHASE II

\*Sold separately

## Engine Type

- Closed-Loop Efi
- Cast-Iron Cylinder Liner
- Aluminum Head And Crankcase
- Four-Cycle
- Gasoline
- Ohv




## Additional Features


- Quad-Clean™ Four-Stage Cyclonic Air Cleaner
- Dual Ball Bearings
- Large Metal Fuel Tank
- Ech440le Includes Catalytic Muffler



## Maximum power

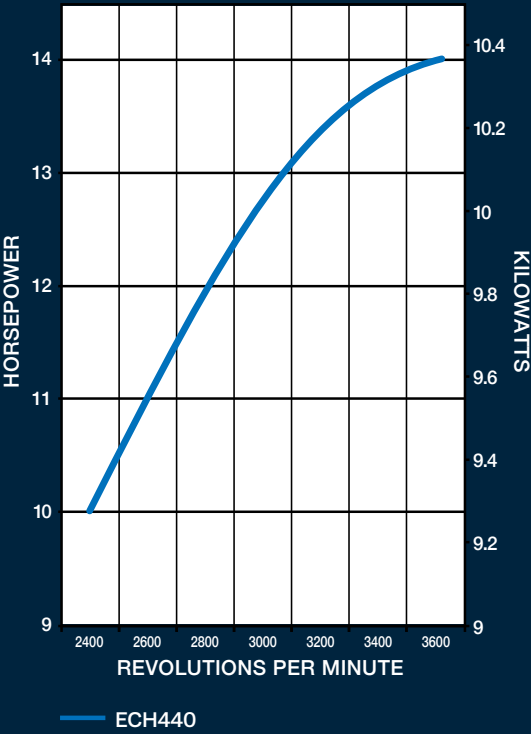

## Maximum torque

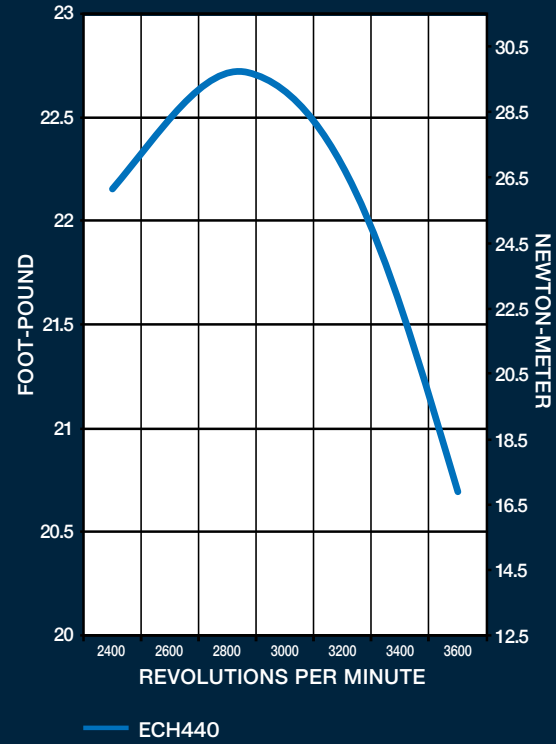



For more information, contact your Rehiko source of supply.  
Discovery Energy, LLC reserves the right to make modifications without prior notice.

[engines.rehiko.com](https://engines.rehiko.com)

Printed in Italy    ED0035585200    Rev.04 07/25 Eng    Discovery Energy, LLC