



Available in four options:

- **Standard Duty Series**
 - Available in five BCI groups: 24, 26, 31, 4D, and 8D
- **Optimum Duty Series**
 - Available in seven BCI groups: 24, 26, 31, 34, 51, 4D, and 8D
- **Heavy Duty Series**
 - Available in six BCI groups: 24, 31, 34, 51, 4D, and 8D
- **Severe Duty Series – AGM**
 - Available in four BCI groups: 24, 31, 4D, and 8D

Applicable to the following:

Industrial
Marine
Mobile/Towable
Residential/Commercial

Battery Features:

- Maintenance-free design eliminates the need for routine maintenance.
- Plate construction utilizes uniform wire thickness across the grid structure to hold and retain active material for more starts and better reliability.
- Heavy-duty terminals resist corrosion and optimize durability and efficiency in tough operating environments.




Generator Set Accessories

Generator Set Batteries

Aftermarket Part Number	BCI Group	Model Description	Electrical Capacity			Dimensions			Weight kg (lbs.)	Post Styles
			Volts	CCA Rating	RC Minutes	Length mm (in.)	Width mm (in.)	Height mm (in.)		
STANDARD DUTY SERIES—12 MONTH WARRANTY										
GM106368-S	24	24-SD	12	550	100	260 (10.2)	173 (6.8)	225 (8.8)	16.8 (37)	D/1
GM106369-S	26	26-SD	12	500	75	208 (8.2)	173 (6.8)	197 (7.8)	11.8 (26)	D/1
GM106698-S	31	31A-SD	12	750	155	330 (13.0)	173 (6.8)	240 (9.4)	21.8 (48)	C/1
GM106370-S	31	31S-SD	12	750	155	330 (13.0)	173 (6.8)	240 (9.4)	21.8 (48)	C/3
GM106371-S	4D	4D-SD	12	1000	300	527 (20.8)	219 (8.6)	254 (10.0)	45.4 (100)	A/1
GM106372-S	8D	8D-SD	12	1100	325	527 (20.8)	283 (11.0)	249 (9.8)	52.2 (115)	A/1
GM123599-S	51	51-SD	12	500	85	238 (9.4)	129 (5.0)	222 (8.8)	12.2 (27)	D/1
GM121727-S	26R	26R-SD	12	500	75	208 (8.2)	173 (6.8)	197 (7.8)	11.8 (26)	D/1
OPTIMUM DUTY SERIES—18 MONTH WARRANTY										
GM106373-S	24	24-OD	12	650	125	260 (10.2)	173 (6.8)	226 (8.8)	18.1 (40)	D/1
GM106680-S	26	26-OD	12	550	100	208 (8.2)	173 (6.8)	197 (7.8)	13.6 (30)	D/1
GM106699-S* GM106375-S	31	31A-OD 31S-OD	12	925	180	330 (13.0)	173 (6.8)	240 (9.4)	24.5 (54)	C/1 C/3
GM106681-S	34	34-OD	12	690	130	260 (10.2)	173 (6.8)	200 (7.8)	16.1 (35)	D/1
GM106374-S	51	51-OD	12	500	85	237 (9.2)	125 (4.8)	220 (8.6)	12.5 (27)	D/1
GM106376-S	4D	4D-OD	12	1300	340	527 (20.8)	219 (8.6)	254 (10.0)	47.6 (105)	A/1
GM106377-S	8D	8D-OD	12	1400	380	527 (20.8)	279 (11.0)	254 (10.0)	56.7 (125)	A/1
GM121580-S	26R	26R-OD	12	550	100	208 (8.2)	173 (6.8)	197 (7.8)	13.6 (30)	D/1
HEAVY DUTY SERIES—24 MONTH WARRANTY										
GM106378-S	24	24-HD	12	800	125	260 (10.2)	171 (6.8)	229 (9.0)	21.8 (48)	D/1
GM106700-S* GM106380-S	31	31A-HD 31S-HD	12	960	190	330 (13.0)	171 (6.8)	238 (9.4)	25.9 (57)	C/1 C/3
GM106682-S	34	34-HD	12	770	115	260 (10.2)	171 (6.8)	208 (8.2)	15.9 (35)	D/1
GM106379-S	51	51-HD	12	510	90	237 (9.2)	125 (5.0)	220 (8.6)	12.5 (27)	D/1
GM106381-S	4D	4D-HD	12	1300	315	527 (10.2)	219 (8.6)	254 (10.0)	47.6 (105)	A/1
GM106382-S	8D	8D-HD	12	1425	400	527 (10.2)	279 (11.0)	254 (10.0)	56.7 (125)	A/1
SEVERE DUTY SERIES—36 MONTH WARRANTY										
GM117040-S	24	24-AGM	12	750	140	286 (11.2)	171 (6.8)	238 (9.4)	23.6 (52)	D/1 D/3
GM121078-S	31	31-AGM	12	950	190	330 (13.0)	172 (6.8)	238 (9.4)	31.8 (70)	C/1 C/3
GM125206-S	4D	4D-AGM	12	1250	380	513 (20.2)	222 (8.8)	216 (9)	50.3 (111)	A/1
GM125286-S	8D	8D-AGM	12	1450	520	525 (20.6)	279 (11)	251 (9.8)	87.3 (192)	A/1
* Automotive Post Style - Service Only Note: For installed and corresponding aftermarket battery replacement options, please reference PB-159".										

Terminal Styles

All batteries are 12 volt, charger type: wet, and lead-calcium construction.

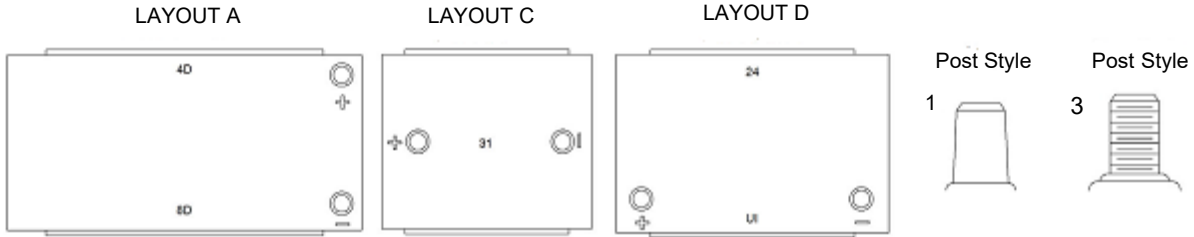

Availability is subject to change without notice. Discovery Energy, LLC reserves the right to change the design or specifications without notice and without any obligation or liability whatsoever. Contact your local Rehko generator set distributor for availability.